


Dimensions

 

CS wall-mounting enclosures with door and blank plate

CS-...

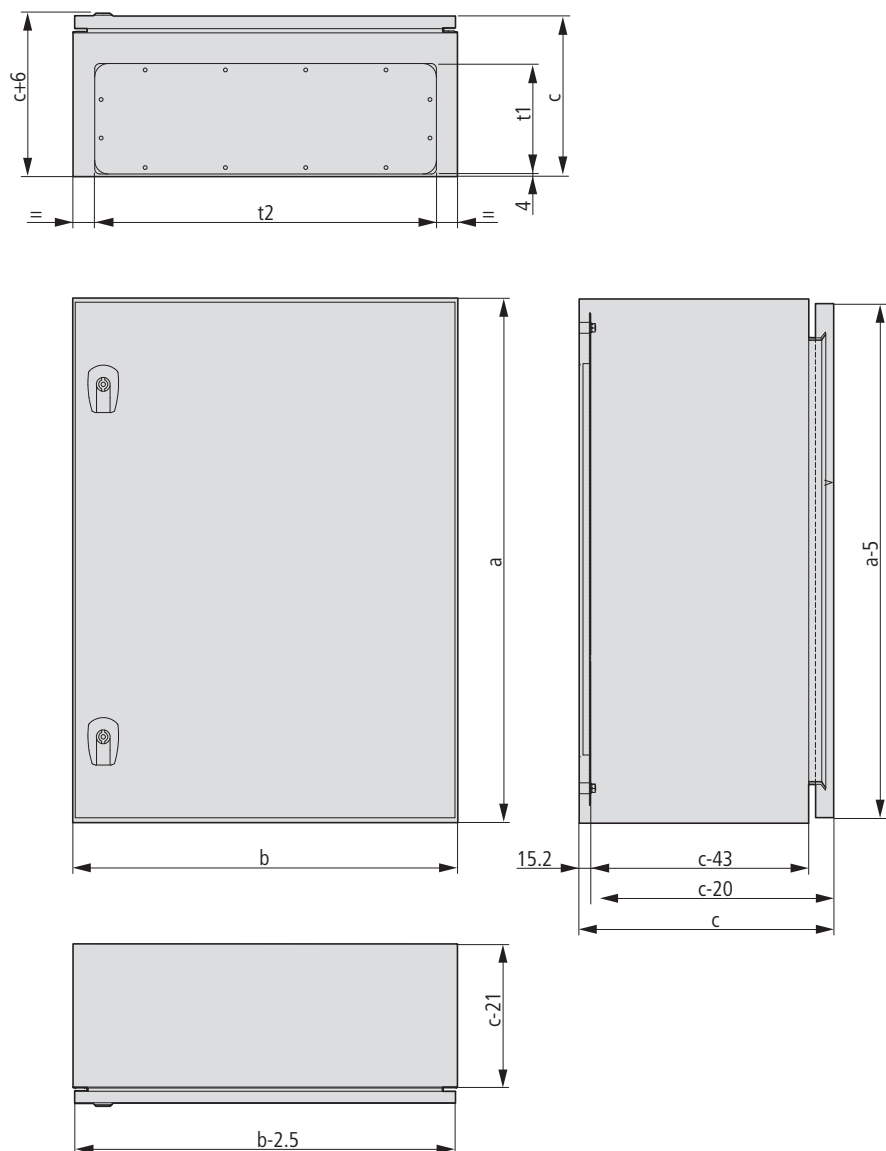

Door for internal separation

DI-...-CS

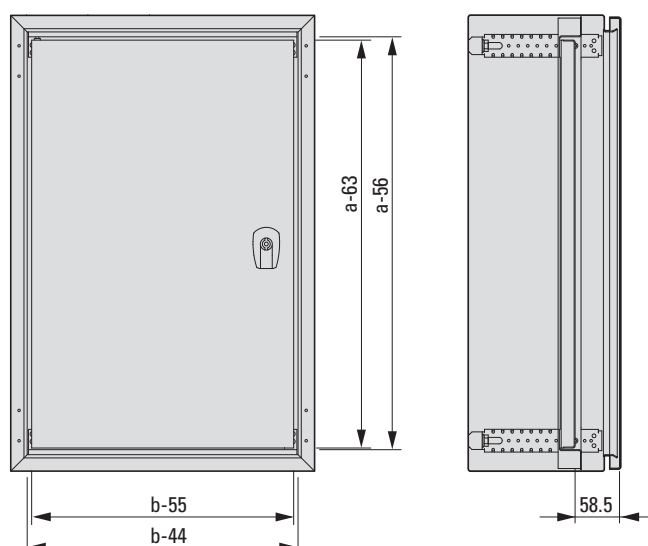


21/26 CS sheet steel wall-mounting enclosure

Interior fittings

CS-..., DS-...-CS

CS wall-mounting enclosures without door, without blank plate


CS-...

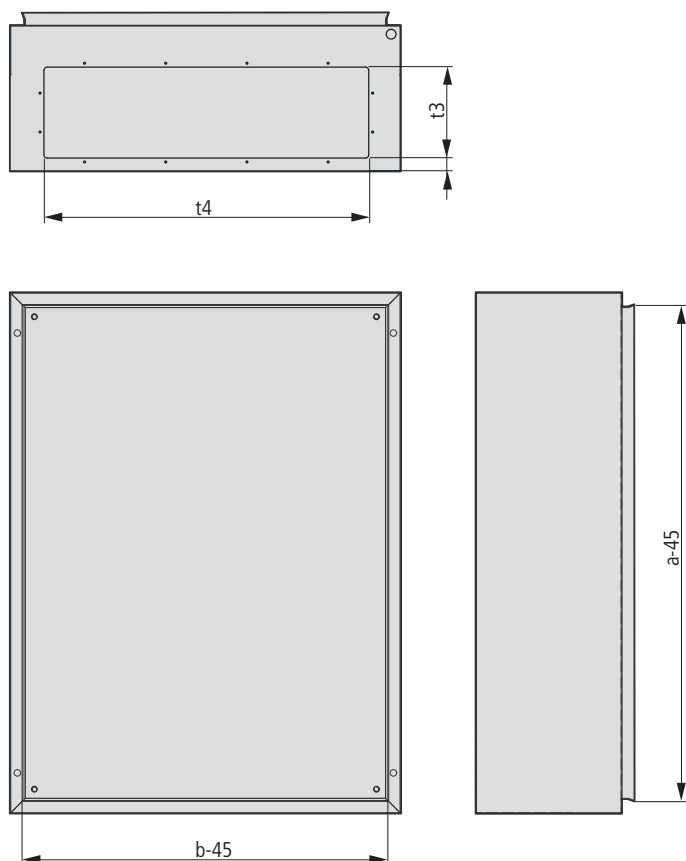

Internal view, door without enclosure


CS-2520/150, CS-32/150

DS-2520-CS, DS-3020-CS

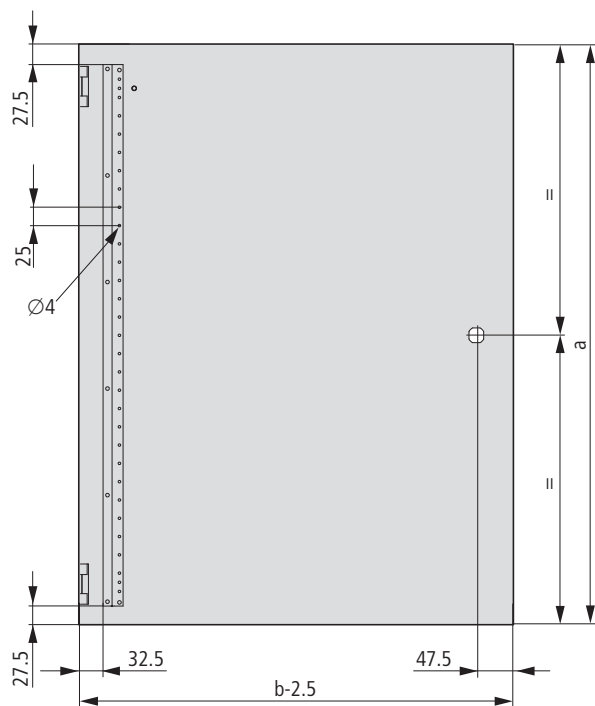

CS-33/..., CS-34/..., CS-4.../...


DS-3030-CS, DS-3040-CS, DS-4...-CS

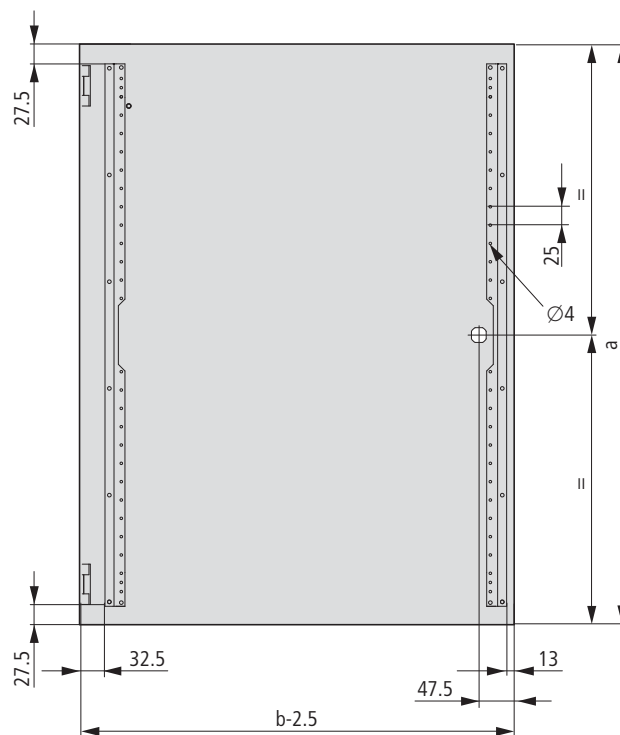

Internal view, door without enclosure


CS-5-.../..., CS-6-.../..., CS-7-.../..., CS-8-.../...

DS-5-...-CS, DS-6-...-CS, DS-7-...-CS, DS-8-...-CS

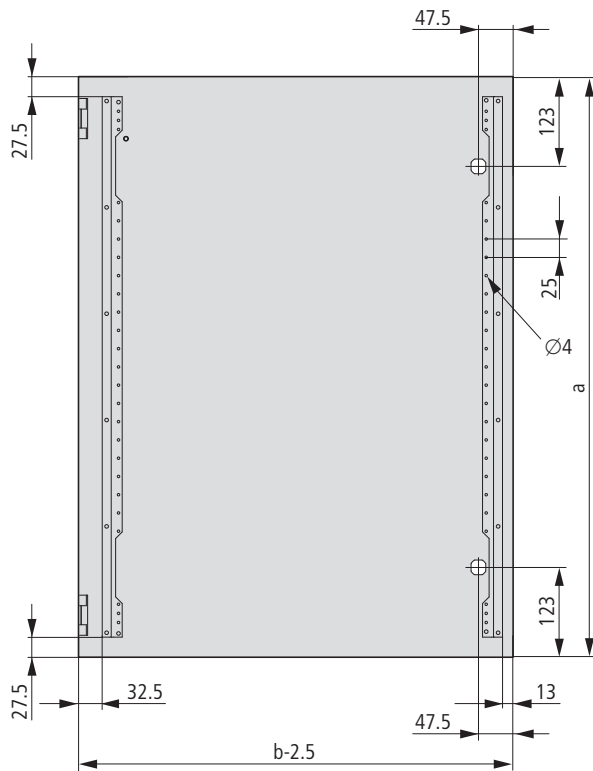

CS-106-.../..., CS-108-.../..., CS-126-.../..., CS-128-.../...


DS-106-.../..., DS-108-.../..., DS-126-.../..., DS-128-.../...

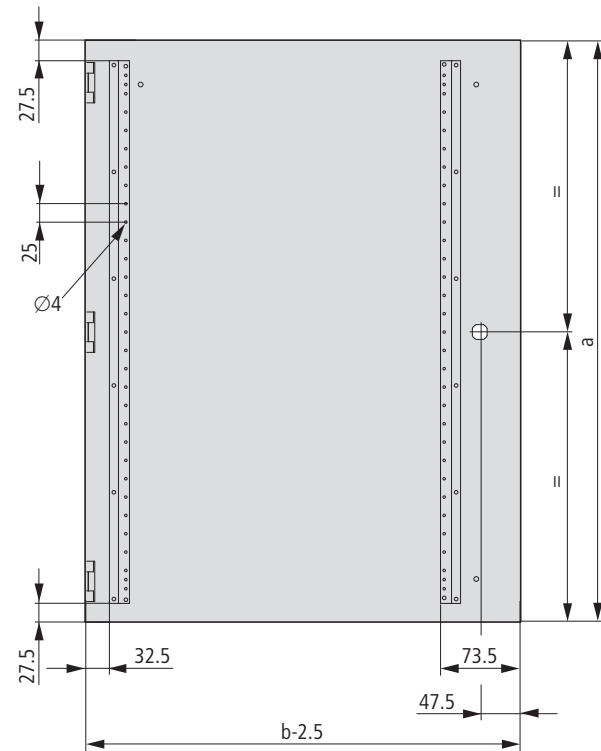

Internal view, door without enclosure


CS-1010-.../..., CS-1210-.../..., CS-1212-.../...

DS-1010-.../..., DS-1210-.../..., DS-1212-.../...

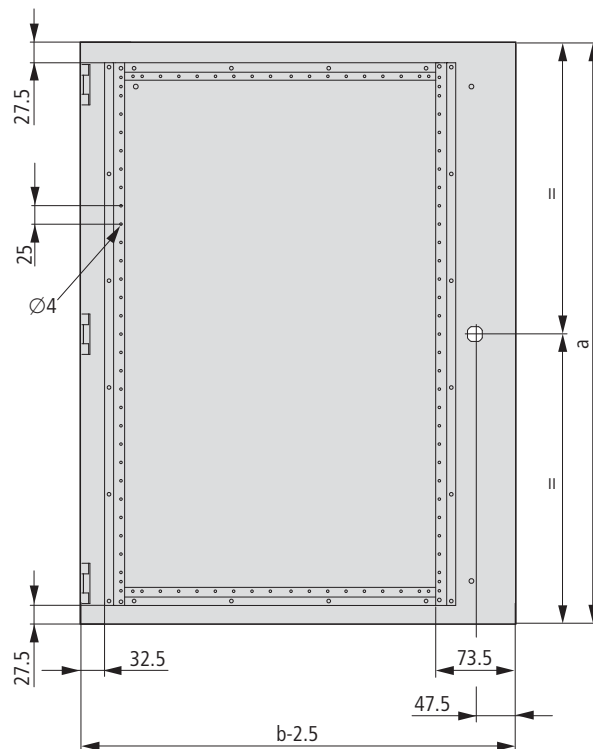


Mounting aperture

CS-...

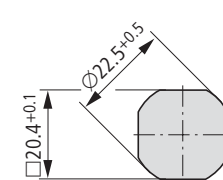


Position of the 4 drilling dimensions for wall fixing in the enclosure rear panel

CS-...

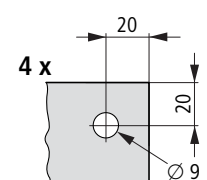

Position of the 4 threaded studs in the enclosure rear panel

CS-...

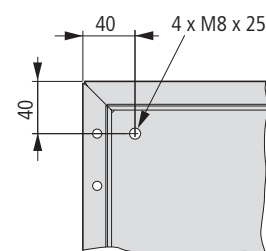

21/28 CS sheet steel wall-mounting enclosure

Interior fittings

CS-..., DS-...-CS

Enclosure dimensions								Door dimensions			
Part no.	a	b	c	t1	t2	t3	t4	Housing		Door	
								Height	Width	Height	Width
CS-2520/150	250	200	150	112	182	80	150	250	200	248	197.5
CS-32/150	300	200	150	112	182	80	150	300	200	298	197.5
CS-33/150	300	300	150	112	232	80	200	300	300	298	297.5
CS-33/200	300	300	200	172	262	140	230	300	400	298	397.5
CS-34/200	300	400	200	172	332	140	300	400	300	398	297.5
CS-43/150	400	300	150	112	232	80	200	400	400	398	397.5
CS-43/200	400	300	200	172	262	140	230	400	600	398	597.5
CS-44/150	400	400	150	112	332	80	300	500	400	498	397.5
CS-44/200	400	400	200	172	332	140	300	500	500	498	497.5
CS-46/200	400	600	200	172	532	140	500	600	400	598	397.5
CS-46/250	400	600	250	172	532	140	500	600	500	598	497.5
CS-46/300	400	600	300	172	532	140	500	600	600	598	597.5
CS-54/150	500	400	150	112	332	80	300	600	800	598	797.5
CS-54/200	500	400	200	172	332	140	300	700	500	698	497.5
CS-54/250	500	400	250	172	332	140	300	800	400	798	397.5
CS-55/250	500	500	250	172	432	140	400	800	600	798	597.5
CS-64/150	600	400	150	112	332	80	300	800	800	798	797.5
CS-64/200	600	400	200	172	332	140	300	800	1000	798	997.5
CS-64/250	600	400	250	172	332	140	300	1000	600	998	597.5
CS-65/150	600	500	150	112	332	80	300	1000	800	998	797.5
CS-65/200	600	500	200	172	432	140	400	1000	1000	998	997.5
CS-65/250	600	500	250	172	432	140	400	1200	600	1198	597.5
CS-66/200	600	600	200	172	532	140	500	1200	800	1198	797.5
CS-66/250	600	600	250	172	532	140	500	1200	1000	1198	997.5
CS-66/300	600	600	300	172	532	140	500	1200	1200	1198	1197.5
CS-68/300	600	800	300	172	732	140	700				
CS-75/200	700	500	200	172	432	140	400				
CS-75/250	700	500	250	172	432	140	400				
CS-84/200	800	400	200	172	332	140	300				
CS-84/250	800	400	250	172	332	140	300				
CS-86/200	800	600	200	172	532	140	500				
CS-86/250	800	600	250	172	532	140	500				
CS-86/300	800	600	300	172	532	140	500				
CS-88/200	800	800	200	172	732	140	700				
CS-88/300	800	800	300	172	732	140	700				
CS-810/300	800	1000	300	172	932	140	900				
CS-106/250	1000	600	250	172	532	140	500				
CS-106/300	1000	600	300	172	532	140	500				
CS-108/250	1000	800	250	172	732	140	700				
CS-108/300	1000	800	300	172	732	140	700				
CS-1010/300	1000	1000	300	172	932	140	900				
CS-126/250	1200	600	250	172	532	140	500				
CS-128/300	1200	800	300	172	732	140	700				
CS-1210/300	1200	1000	300	172	932	140	900				
CS-1212/250	1200	1200	250	2 x 172	532	140	500				


Hole center distance between two door support bars

Door width b	Hole center distance
300	203.4
400	303.4
500	403.4
600	503.4
800	703.4
1000	903.4
1200	1103.4




Doors with an inspection glass

DT-...-CS

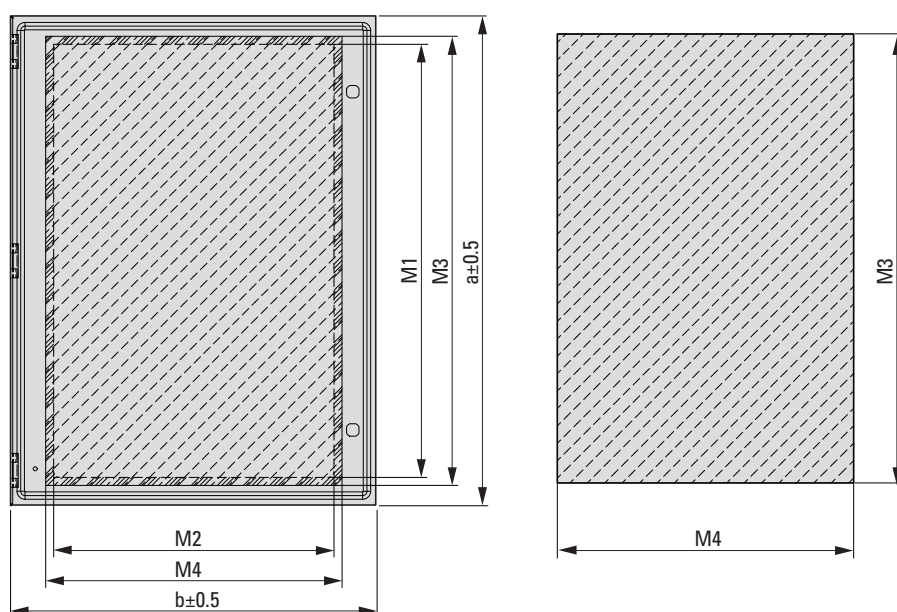


Enclosure		Door			
a	b	M1	M2	M3	M4
250	200	132	84	158	110
250	250	152	104	178	130
300	200	182	84	208	110
300	250	202	104	228	130
300	300	202	154	228	180
300	400	202	254	228	280
400	300	302	154	328	180
400	400	302	254	328	280
400	500	302	354	328	380
400	600	302	454	328	480
500	300	402	154	428	180
500	400	402	254	428	280
500	500	402	354	428	380
600	400	502	254	528	280
600	500	503	355	529	381
600	600	503	455	529	481
600	800	503	655	529	681
700	500	603	355	629	381
800	400	703	255	729	281
800	600	703	455	729	481
800	800	703	655	729	681
800	1000	703	855	729	881
1000	600	904	425	930	451
1000	800	904	625	930	651
1000	1000	904	825	930	851
1200	600	1104	425	1130	451
1200	800	1104	625	1130	651
1200	900	1104	725	1130	751
1200	1000	1104	825	1130	851
1200	1200	1104	1025	1130	1051

 


F3A enclosure base with flange apertures


300 x 200

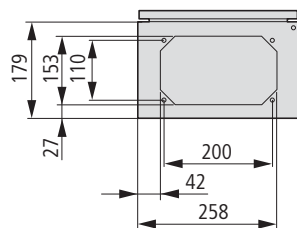


400 x 200

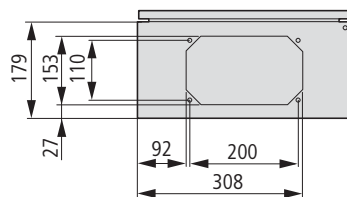


500 x 200

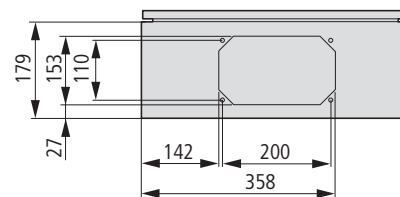


600 x 200

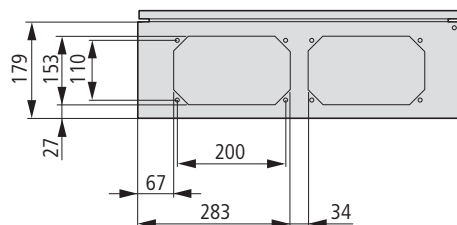


400 x 250

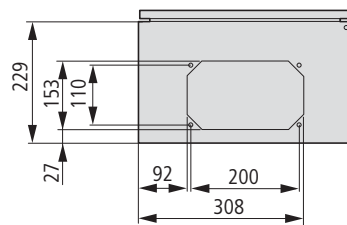


500 x 250

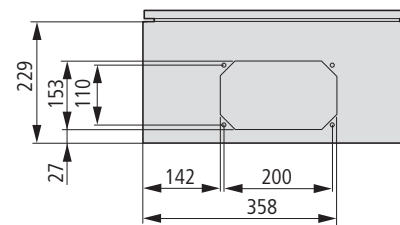


600 x 250

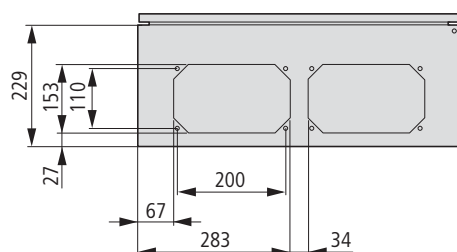


600 x 300

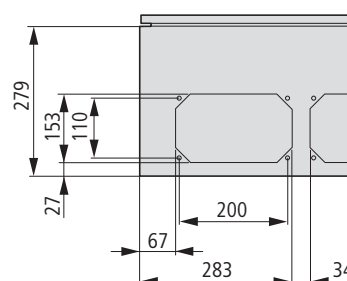


800 x 200

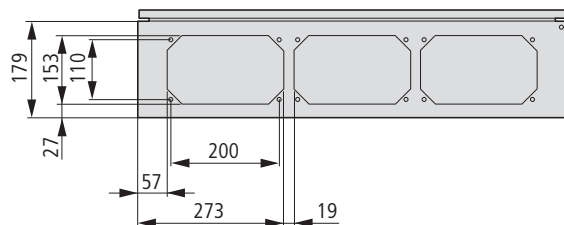


800 x 250

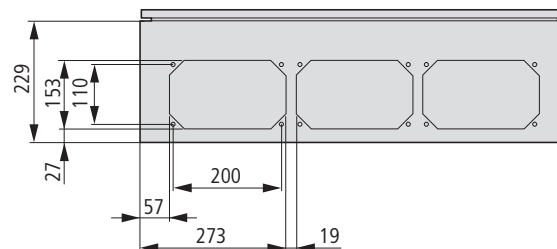


800 x 300

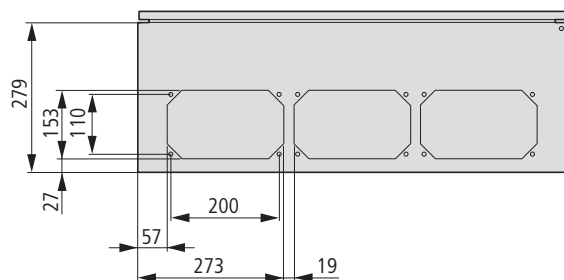

1000 x 300

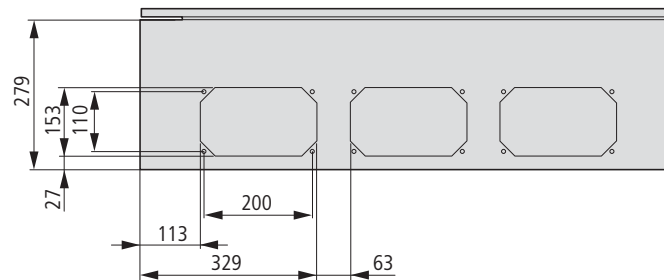


1200 x 250

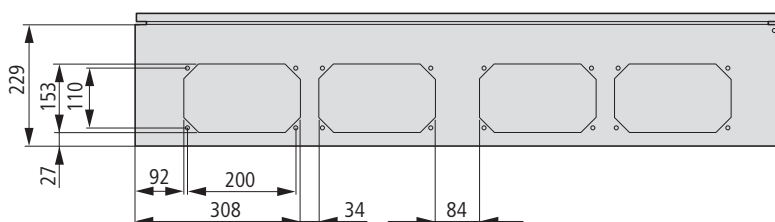


Blank plate (equipment supplied)


300 x 200

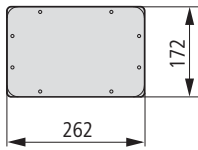


400 x 200

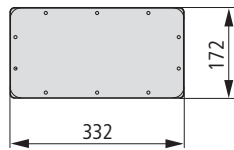


500 x 200

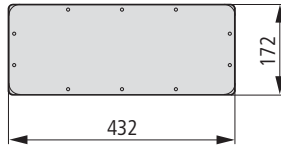


600 x 200

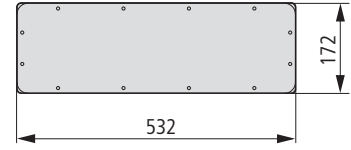

800 x 200

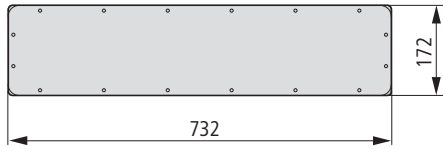

1000 x 200

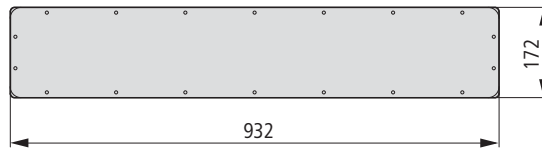


Mounting plates

MPP-...-CS

MPL-.../RAL2000-CS

MPL-...-CS

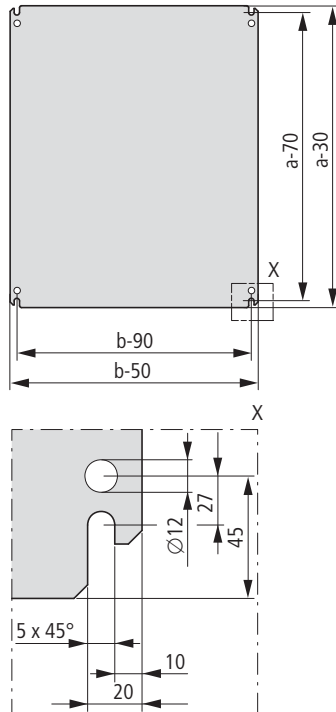


a, b = Enclosure dimensions

Part no.	Mounting plate	
	Height	Width
CS-2520/150	220	150
CS-32/150	270	150
CS-33/150	270	250
CS-33/200	270	250
CS-34/200	270	350
CS-43/150	370	250
CS-43/200	370	250
CS-44/150	370	350
CS-44/200	370	350
CS-46/200	370	550
CS-46/250	370	550
CS-46/300	370	550
CS-54/150	470	350
CS-54/200	470	350
CS-54/250	470	350
CS-55/250	470	450
CS-64/150	570	350
CS-64/200	570	350
CS-64/250	570	350
CS-65/150	570	450
CS-65/200	570	450
CS-65/250	570	450
CS-66/200	570	550
CS-66/250	570	550
CS-66/300	570	550
CS-68/300	550	770
CS-75/200	670	450
CS-75/250	670	450
CS-84/200	770	350
CS-84/250	770	350
CS-86/200	770	550
CS-86/250	770	550
CS-86/300	770	550
CS-88/200	770	750
CS-88/300	770	750
CS-810/300	770	950
CS-106/250	970	550
CS-106/300	970	550
CS-108/250	970	750
CS-108/300	970	750
CS-1010/300	970	950
CS-126/250	1170	550
CS-128/300	1170	750
CS-1210/300	1170	950
CS-1212/250	1170	1150


Mounting rail module for soft starters

TS35-DS4-CS

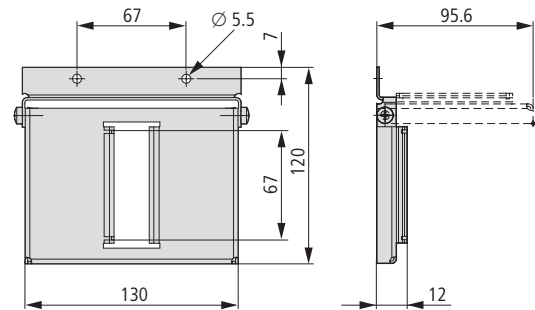


Depth-adjustment elements for mounting plates

DAS-SET/...-CS

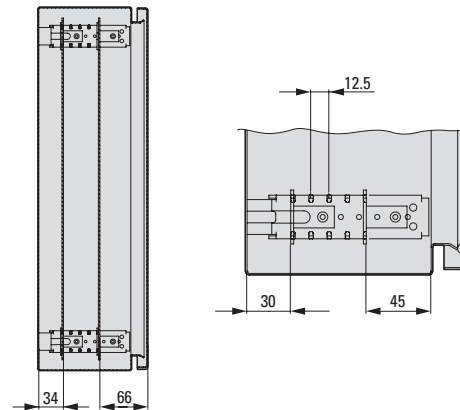

Mounting webs for door profile bars and cable ducts

MTR-D...-CS

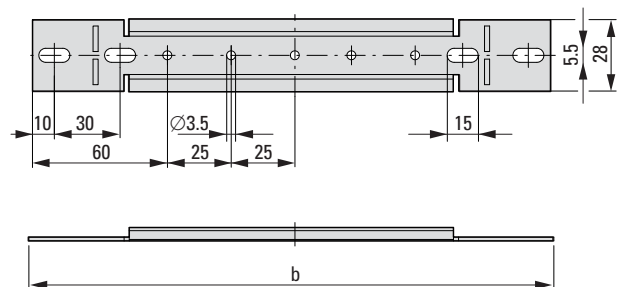

Part no.	b
MTR-D3-CS	220
MTR-D4-CS	320
MTR-D5-CS	420
MTR-D6-CS	520
MTR-D8-CS	720




21/32 CS sheet steel wall-mounting enclosure

Exterior fittings

WFB, AFP, F3A


Wall fixing bracket

WFB-SET-CS

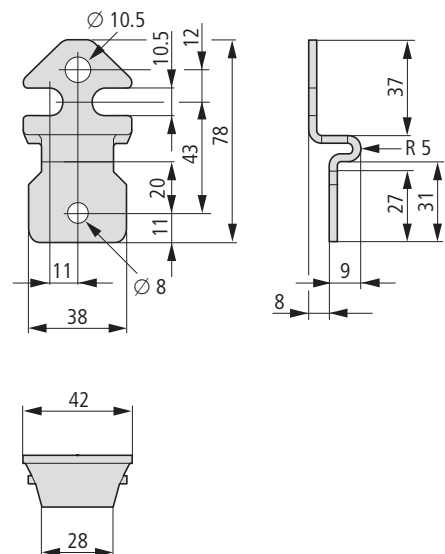

Set of lifting eyebolts with profile brackets


TOR-SET/135-CS

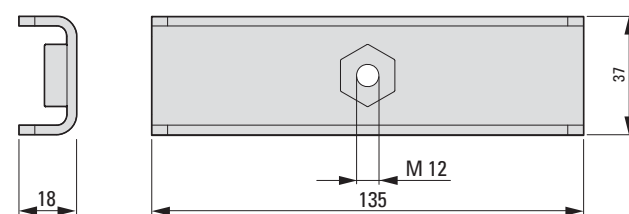

Base panels with flange apertures (for F3A-...flange)

AFP-3-CS

AFP-4-CS

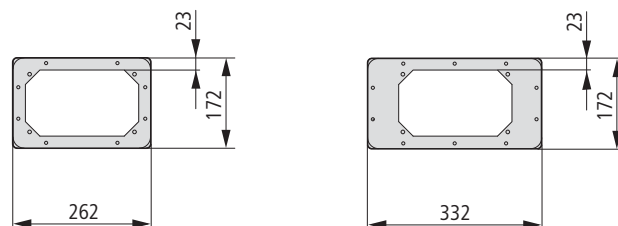


Base panels with flange apertures (for F3A-...flange)

AFP-5-CS


AFP-6-CS

AFP-12-CS = 2 x AFP-6-CS

AFP-8-CS

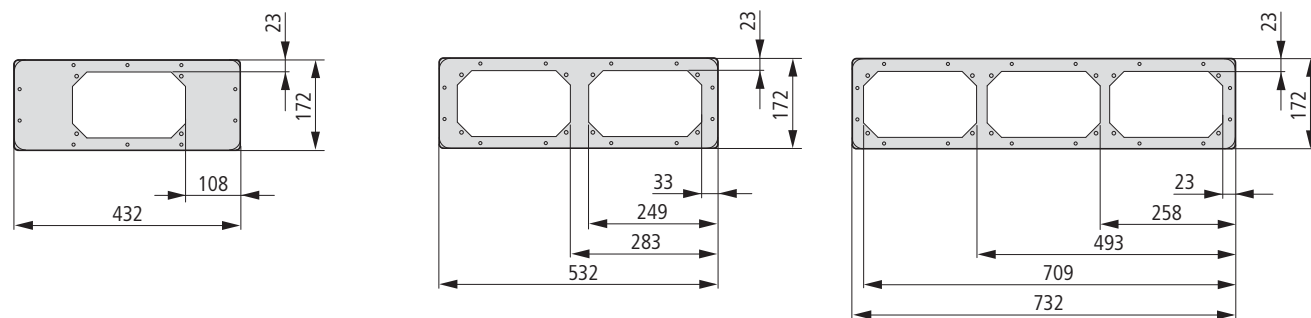


AFP-10-CS

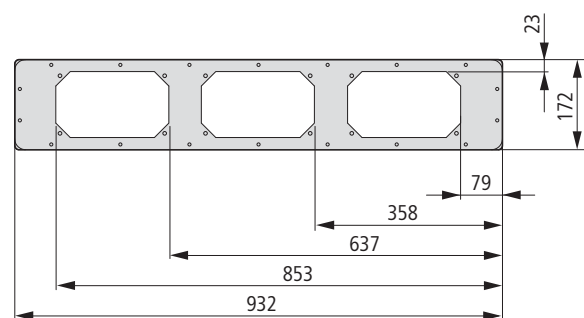


Flanges

F3A-...

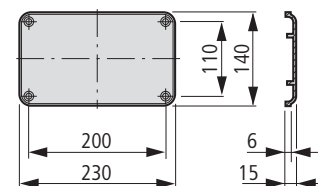


Flange aperture

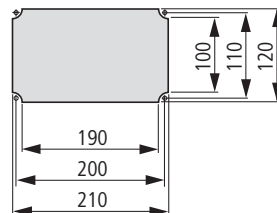

Rain canopies

CNP-...-CS

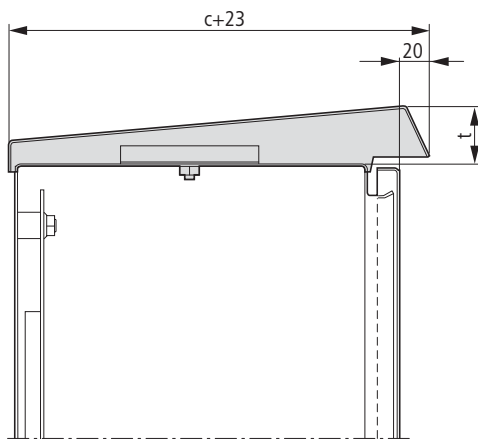


c = Enclosure depth


Part no.	c + 23	t
CNP-2/150-CS	173	30
CNP-3/150-CS	173	30
CNP-3/200-CS	223	34
CNP-4/150-CS	173	30
CNP-4/200-CS	223	34
CNP-4/250-CS	273	38
CNP-5/150-CS	173	30
CNP-5/200-CS	223	34
CNP-5/250-CS	273	38
CNP-6/200-CS	223	34
CNP-6/250-CS	273	38
CNP-6/300-CS	323	42
CNP-8/200-CS	223	34
CNP-8/250-CS	273	38
CNP-8/300-CS	323	42
CNP-10/300-CS	323	42
CNP-12/250-CS	273	38

Ventilating louvers


LVP-20V12-CS

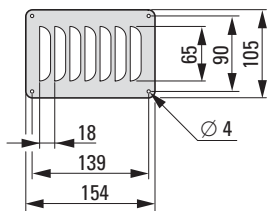


LVP-20H12-CS

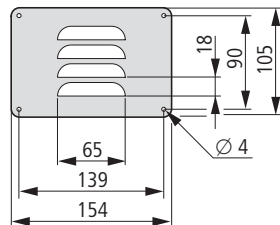

LVP-30V15-CS

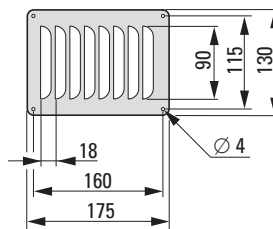


LVP-30H15-CS

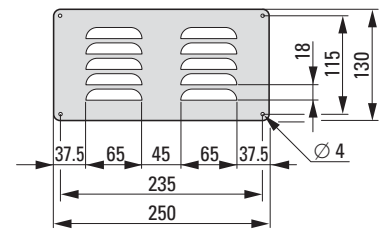


Cable interconnect base

PLI-/...-200-CS

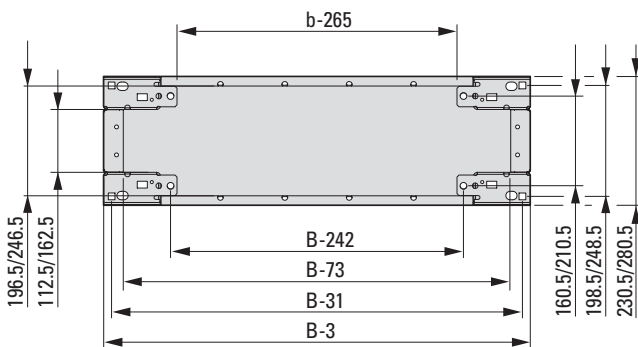

Fixing on a mast

MAST-FIT-CS

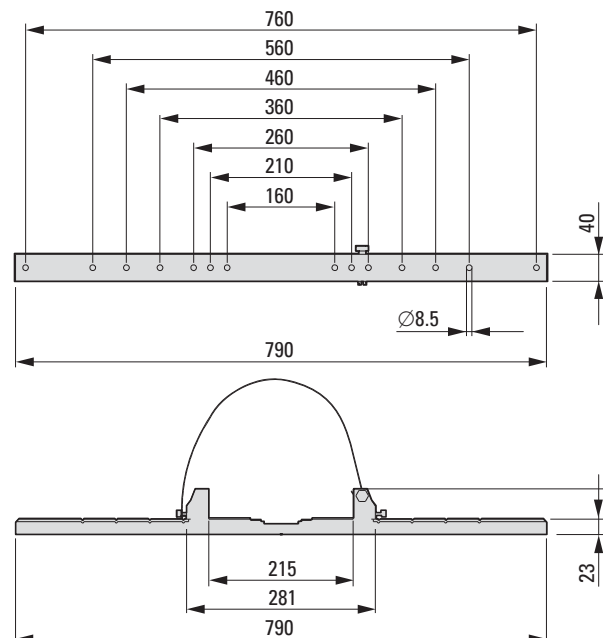

Cable glands, ventilation cable glands, cable grommets

→ See chapter 16, Accessories for panel building





